

AUTO LINK PAL FUSES - 2935

RoHS



Description


PAL fuses are commonly found on many Japanese and domestic built vehicles.

Ratings

| Part Number | Current Rating (A) | Body Color |
|-------------|--------------------|-------------|
| 0293525._ | 25 | LIGHT BROWN |
| 0293530._ | 30 | LIGHT GREEN |
| 0293545._ | 45 | RED |
| 0293565._ | 65 | BLACK |
| 0293575._ | 75 | GRAY |

Dimensions (25A - 30A)

Dimensions in mm

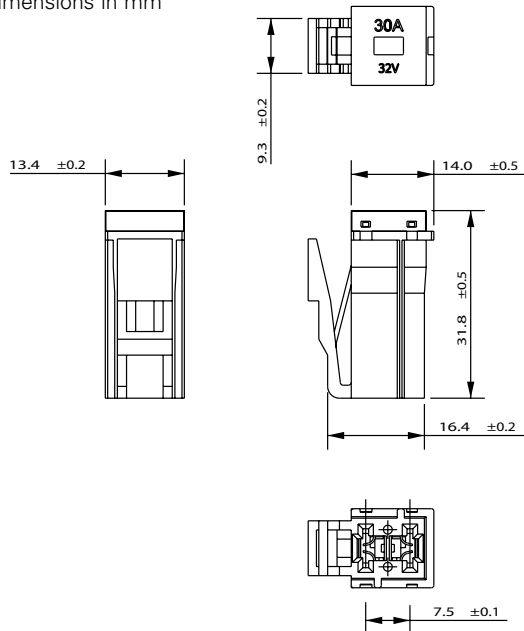

Specifications

Voltage Rating: 32 VDC
 Current Cycling: 24°C
 The fuses satisfy the performance requirements after 50% of the rated current is applied for 10,000 cycles. Each cycle consists of an interrupted current with the pattern of 5 minutes ON and 10 minutes OFF.
 Operating Temperature Range: -40°C to +125°C

Complies with JASO 0612

Ordering Information

| Part Number | Package Size |
|-------------|--------------|
| 02935xx.H | 100 |
| 02935xx.U | 500 |
| 02935xx.MXJ | 1000 |

Time-Current Characteristics

| % of Rating | Opening Time Min / Max (s) | |
|-------------|----------------------------|------------|
| | 25A - 30A | 45A - 75A |
| 110 | - / - | 14,400 s |
| 150 | - / - | 100 s |
| 200 | 5 s / 70 s | 2 s / 60 s |
| 300 | - / 6 s | - / 5 s |
| 600 | - / 3 s | - / 2 s |

Dimensions (45A - 75A)

Dimensions in mm

