

520/521/102071 Series Circuit Board Mount Clips for 5mm and 6.3mm Diameter Fuses




520 Clip

521 Clip
(90° Pin Shift)


102071 Clip

Product Dimensions


520 Clip

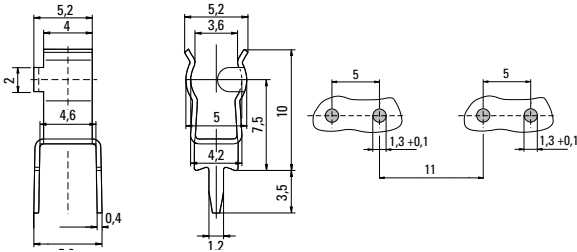

521 Clip

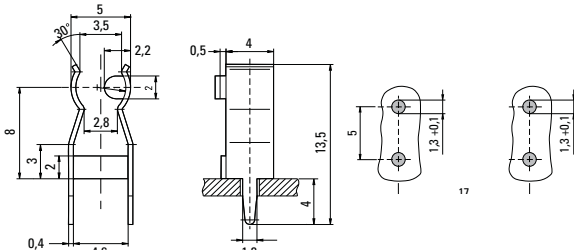

102071 Clip

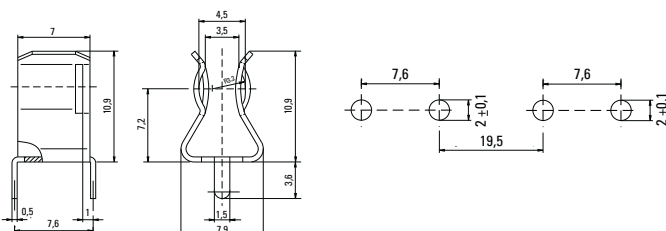

Product Characteristics			
	520 Clip	521 Clip	102071 Clip
Compatible Fuse Size	5mm Diameter		6.3mm Diameter
Electrical Data (23°C)	Rated Voltage: 250V		Rated Voltage: 500V
	Max. Current/Power: 6.3A/2.5W		Max. Current/Power: 10A/4W
Mounting	PC Board, 5mm pin spacing Solder pins 0.4×1.2mm		PC Board, 7.6 mm pin spacing Solder pins 0.5×1.5 mm
Solderability	235°C, 2 sec. (IEC 60068-2-20)		
Soldering Heat Resistance	260°C, 10 sec. (IEC 60068-2-20)		
Minimum Cross Section	Conducting path - 0.2mm ²		
Unit Weight	0.4g		0.9g
UL Agency Approval	N/A	N/A	N/A

Ordering Information			
Ordering PN	Clip Material	Plating	Packaging Available
5200001009	Phos Bronze	Tin plated	Bulk 2000
5210001009	Phos Bronze	Tin plated	Bulk 2000
10207101009	Brass	Tin plated	Bulk 1000