



## 155 Series Twist-Lock In-Line Holders for 3AG/AB Fuses

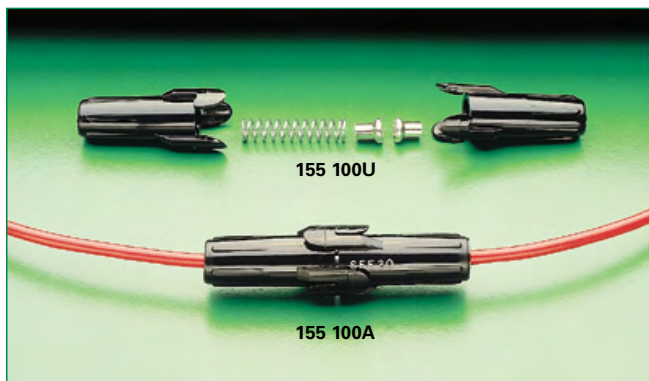

### Dimensions

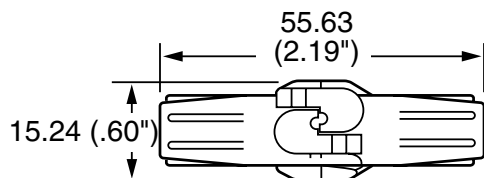

### Product Characteristics

Compatible Fuses	For low voltage 3AG/AB or SFE Fuse Applications
<b>Electrical</b>	Intended for use at 32 volts or less with fuses rated up to 20 amperes when the proper spring is installed for fuse size.
<b>Molded Parts</b>	Black Thermoplastic (UL94 V-2). Body halves have a .14" diameter hole for insulated wire.
<b>Ambient Temperature</b>	-40°C to +75°C.
<b>Contact Rivet</b>	Brass. Nickel plating. Designed to accommodate #14 AWG stranded wire.
<b>Assembled</b>	Supplied with 19" loop of #14 AWG red vinyl insulated wire, SFE fuse (listed) with a spring in different lengths depending of the fuse size.
<b>Unassembled</b>	For assembly to #14 AWG wire.
<b>Options</b>	150 215 is similar to 155 120A except no fuse is supplied. It is intended for use with 3AG fuses rated up to 20 amperes.
<b>In-Line Fuseholder</b>	Supplied with a spring in different lengths depending of the fuse size.

\* Please refer to Fuseology section for information on proper fuseholder re-rating.

\*\* Fuseholders with specific wire sizes and lengths are available on special order.

### Additional Information



Datasheet



Resources




Samples

### Ordering Information


Unassembled			Assembled			Packaging
Ordering Number	Catalog Number	For Fuse Size	Ordering Number	Catalog Number	Fuse Installed	
-	<b>155 100</b>	All below	<b>01550100Z*</b>	-	-	Bulk Pack (100 Pcs)
<b>01550104ZXU</b>	<b>155 104U</b>	¼" × 5/8"	<b>01550104ZXA</b>	<b>155 104A</b>	SFE 4	Bulk Pack (100 Pcs - Assembled) (100 Pcs- Unassembled)
<b>01550106ZXU</b>	<b>155 106U</b>	¼" × ¾"	<b>01550106ZXA</b>	<b>155 106A</b>	SFE 6	Bulk Pack (100 Pcs - Assembled) (100 Pcs- Unassembled)
<b>01550109ZXU</b>	<b>155 109U</b>	¼" × 7/8"	<b>01550109ZXA</b>	<b>155 109A</b>	SFE 9	Bulk Pack (100 Pcs - Assembled) (100 Pcs- Unassembled)
<b>01550114ZXU</b>	<b>155 114U</b>	¼" × 1 1/16"	<b>01550114ZXA</b>	<b>155 114A</b>	SFE 14	Bulk Pack (100 Pcs - Assembled) (100 Pcs- Unassembled)
<b>01550120ZXU</b>	<b>155 120U</b>	¼" × 1 ¼"	<b>01550120ZXA</b>	<b>155 120A</b>	SFE 20	Bulk Pack (100 Pcs - Assembled) (100 Pcs- Unassembled)
-	-	¼" × 1 1/16" ¼" × 1 ¼"	<b>01500215Z</b>	-	-	Bulk Pack (100 Pcs)

\* Supplied with 8" loop of #14 AWG red vinyl insulated wire and two springs in different lengths to accommodate SFE sized fuses. (Fuse not included)

## 155 Series Heavy-Duty Bayonet Knob In-Line Holders for 3AG/AB Fuses

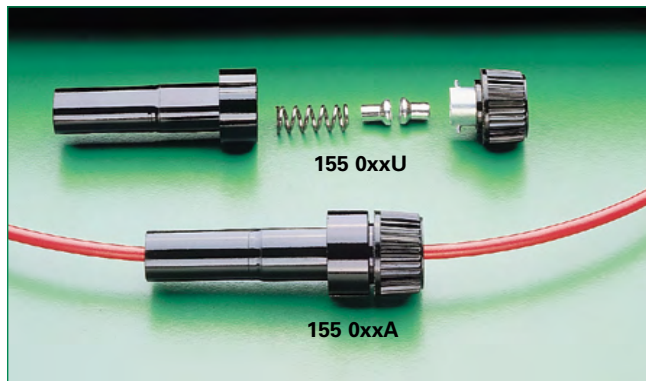

### Dimensions

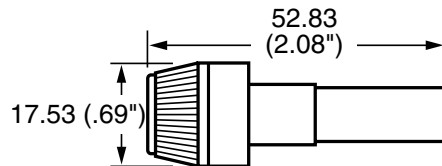

### Product Characteristics

Compatible Fuses	For Low voltage 3AG/AB or SFE Fuse Applications
<b>Electrical</b>	Intended for use at 32 volts or less with fuses rated up to 20 amperes when the proper spring is installed for full size.
<b>Molded Parts</b>	Body and knob are Black Thermoset (UL94 V-0). Both body and knob have a .20" diameter hole for insulated wire.
<b>Knob</b>	Bayonet-lock type metal insert.
<b>Ambient Temperature</b>	-40°C to +125°C.
<b>Contact Rivet</b>	Brass. Tin plated. Designed to accommodate #14 AWG stranded wire.
<b>Assembled</b>	Supplied with 19" loop of #14 AWG red vinyl insulated wire, SFE fuse (listed) with a spring in different lengths depending of the fuse size.
<b>Unassembled</b>	For assembly to #14 AWG wire.
<b>Options</b>	150 079 is similar to 155 020A except no fuse is supplied. It is intended for use with 3AG fuses rated up to 20 amperes.
<b>In-Line Fuseholder</b>	Supplied with a spring in different lengths depending of the fuse size.

\* Please refer to Fuseology section for information on proper fuseholder re-rating.

\*\* Fuseholders with specific wire sizes and lengths are available on special order.

### Additional Information



Datasheet



Resources



Samples

### Ordering Information

Unassembled			Assembled			Packaging
Ordering Number	Catalog Number	For Fuse Size	Ordering Number	Catalog Number	Fuse Installed	
01550004ZXU	155 004U	¼" × 5/8"	01550004ZXA	155 004A	SFE 4	Bulk Pack (100 Pcs)
01550006ZXU	155 006U	¼" × ¾"	01550006ZXA	155 006A	SFE 6	Bulk Pack (100 Pcs)
01550009ZXU	155 009U	¼" × 7/8"	01550009ZXA	155 009A	SFE 9	Bulk Pack (100 Pcs)
01550014ZXU	155 014U	¼" × 1 1/16"	01550014ZXA	155 014A	SFE 14	Bulk Pack (100 Pcs)
01550020ZXU	155 020U	¼" × 1 ¼"	01550020ZXA	155 020A	SFE 20	Bulk Pack (100 Pcs)
-	-	¼" × 1 ¼"	01500079Z	-	-	Bulk Pack (100 Pcs)
-	-	¼" × 1 ¼"	01500145HXB*	-	-	Bulk Pack (100 Pcs)
-	-	¼" × 7/8"	01500145Z**	-	-	Bulk Pack (100 Pcs)
		¼" × 1 1/16"				
		¼" × 1 ¼"				

\* Supplied with 15" loop of #14 AWG red vinyl insulated wire

\*\* and three springs in different lengths to accommodate SFE sized fuses.


## 150 Series In-Line Holders for 2AG or 5×20mm Fuses



### Agency Approval

Agency	Agency File Number
	E14721

### Dimensions [mm]

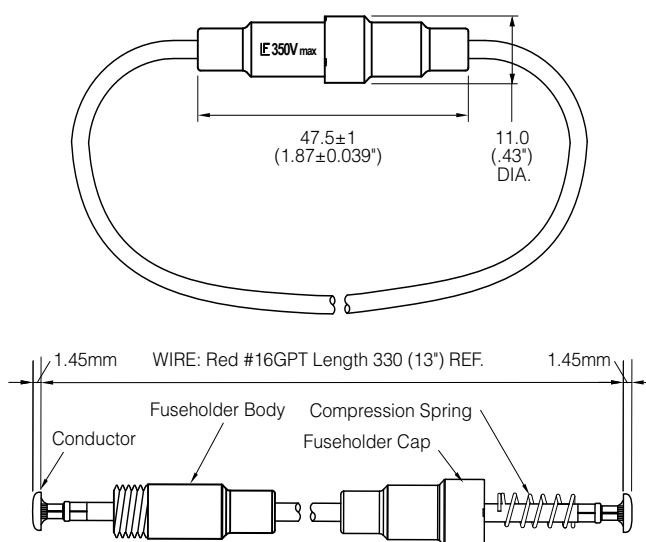

### Product Characteristics

Compatible Fuses	2AG or 5×20mm
<b>Electrical</b>	This fuseholder, part number 150274, is intended for use with 2AG and 5 × 20mm fuses. Maximum current ratings are 5 amperes at 350V for the 2AG size fuses and 10 amperes at 350V for the 5 × 20mm size fuses.**
<b>Body</b>	Black Nylon, UL94 V-0
<b>Terminals</b>	Brass
<b>Wire</b>	16 Awg size; Nominal o.d. 0.104"; color Red
<b>Lead Pull Test</b>	Will withstand 10 lb. pull.
<b>Ambient Temperature</b>	-40°C to +80°C.

#### NOTES:

\* Ensure that proper fuse re-rating is factored in fuseholder selection.

\*\* If use above 32V, power must be turn off when changing the fuse.

### Ordering Information

Ordering Number	Packaging
<b>01500274Z</b>	Bulk Pack (1000 Pcs)
<b>01500274LXN</b>	Bulk Pack (100 Pcs)
<b>*01500274ZXU</b>	Bulk Pack (5000 Pcs)

#### NOTES:

\* For unassembled Fuseholder, UL certification does not apply.

### Additional Information



**Datasheet**



**Resources**



**Samples**